




# YGHP29C2 Figure 6 Compression Grounding Connector

By Burndy  
Catalog # YGHP29C2

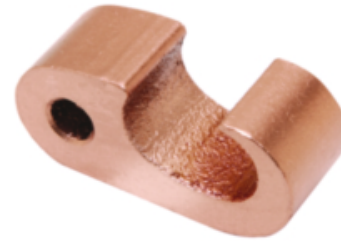

Cu Compression Ground Rod Connector, #4 Sol - #2 Str, 1/2" - 5/8" Rod Dia.

## Application

For Direct Burial In Earth And Concrete

## General

Connector Type	Tap
Die Index	997
EU RoHS Indicator	Yes
Material	Copper
Oxide Inhibitor Type	Penetrox E
Physical Attribute - Number of Crimps Required	1
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	HYTAP
Trade Name	HYTAP™
Type	Taps
UPC	781810220924
UPC 12 Digit	7818102209244

## Dimensions

Dimension - B Length fraction	3/4 in
Dimension - B Length inch	0.75 in

## Conductor Related

Conductor - Copper Solid Tap	4 AWG
Conductor - Copper Solid Tap Range	4 AWG
Conductor - Copper Str Run	1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Run Range	1/0 -250 kcmil
Conductor - Copper Str Tap	4 AWG;3 AWG;2 AWG
Conductor - Copper Str Tap Range	4 AWG-2 AWG
Conductor - Rebar Run	3 ;4
Conductor - Rebar Run Range	3 -4
Conductor - Rod Run	1/2 in;5/8 in
Conductor - Rod Run Range	1/2 in-5/8 in

## Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	<ul style="list-style-type: none"> <li>• UL467</li> <li>• IEEE 837</li> <li>• IEEE 837 2014 Qualified</li> </ul>
Standards - Industry Standards Met	UL467;IEEE 837;IEEE 837 2014 Qualified
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	25
Minimum Pack Quantity	1
Pallet Quantity	7350

## Product Assets

- [3D Models - YGHP29C2\\_MODEL-IGES](#)
- [3D Models - YGHP29C2\\_MODEL-STEP](#)
- [3D Models - YGHP29C2\\_MODEL-PDF](#)
- [Catalogs - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Sales Drawings - sd082473-01](#)



A proud member of the Hubbell Family.

