

Decorator Standard Grade Receptacles

2P3W Grounding
15A 125V



INDUSTRIAL
COMMERCIAL
RESIDENTIAL

B-8
DECORATOR
DEVICES

TESTING & CODE COMPLIANCE

- Meets all UL 498 requirements, (file no. E15058), Fed. Specs. WC-596G.
- CSA Certified, C22.2 no. 42.
- Standard Grade: (file no. 6914 (6233-01))
- NOM Certified

MATERIAL CHARACTERISTICS

Meets flammability requirements per UL94, V2 rated.

Temperature Rating: Standard Grade -40°C to 65°C.

Duplex Receptacles

FEATURES


- Longer, wider strap provides 40% more contact area to wall board. Virtually eliminates floating installations.
- Patented built-in wire stripper for #14 and #12 wire to speed installation.
- Patented built-in wire looper for pre-looping.
- Combination slot/Phillips head mounting and terminal screws ease installation with power screwdrivers. (Slot/Robertson screws in Canada where available).
- Terminal screws backed out – ready for wiring.
- Side wire terminals accept up to #10 solid or stranded wire.
- Push-in terminals accept #14 solid wire.

Side Wire and Push Wire

Rating A	V/AC	NEMA	Color	Catalog No.
15	125	5-15R	Almond	1107A
			Brown	1107B
			Gray	1107GY
			Ivory	1107V
			Light Almond	1107LA
			White	1107W

Automatic Grounding – Side Wire and Push Wire

Rating A	V/AC	NEMA	Color	Catalog No.
15	125	5-15R	Almond	1107-9A
			Black	1107-9BK
			Brown	1107-9B
			Gray	1107-9GY
			Ivory	1107-9V
			Light Almond	1107-9LA
			White	1107-9W

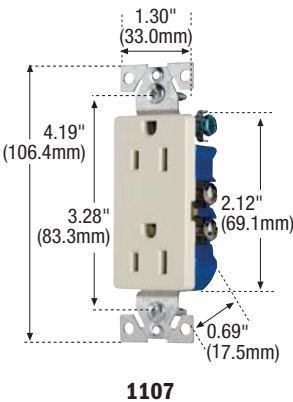

5-15R